


EQ-P1020-DF

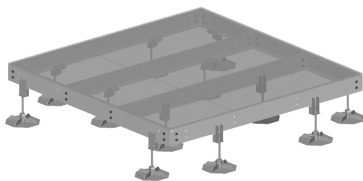

Equipment Platform, 10 ft x 20 ft, base with twenty displacement legs

Product Classification

Product Type Equipment platform system

Dimensions

Length 6.1 m | 20.0 ft
Width 3.0 m | 10.0 ft
Height 546.1 mm | 21.5 in
Weight 1593.6 kg | 3513.3 lb

Environmental Specifications

Load Capacity Up to 10,000 lb (4536 kg) loading

General Specifications

Includes Frame | Grating | Hardware | Legs
Legs, quantity 20
Material Type Hot dip galvanized steel
Package Quantity 1

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system



Included Products

EQ-P1020-B — Equipment Platform, 10 ft x 20 ft, base only
EQ-P-DF — Weight Dispersement Leg for Equipment Platform

EQ-P1020-B



Equipment Platform, 10 ft x 20 ft, base only

Product Classification

Product Type Equipment platform system

Dimensions

Length 6.1 m | 20.0 ft
Width 3.0 m | 10.0 ft
Height 203.2 mm | 8.0 in
Weight 1363.5 kg | 3006.0 lb

Environmental Specifications

Load Capacity Up to 10,000 lb (4536 kg) loading


General Specifications

Includes Frame | Grating | Hardware
Legs, quantity 0
Material Type Hot dip galvanized steel
Package Quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



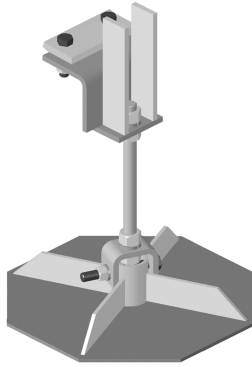

Weight Dispersement Leg for Equipment Platform

Product Classification

Product Type Equipment platform system

Dimensions

Length 393.7 mm | 15.5 in
Width 393.7 mm | 15.5 in
Height 538.5 mm | 21.2 in
Weight 15.3 kg | 33.7 lb

General Specifications

Includes Legs
Material Type Hot dip galvanized steel
Package Quantity 1

Outline Drawing

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system

