

EM0055-000 | FOSC100-BM-72



FOSC® 100C Fiber Optic Splice Closure, Heat Shrink Cable sealing, 72 splices

Product Classification

Regional Availability	Latin America
Product Type	Single-ended, round fiber closure
Product Brand	FOSC®
Product Series	FOSC 100

General Specifications


Cable Entry Drop Port Style	Round
Cable Entry Main Port Style	Oval
Cable Ports Quantity, total	1 oval port (2 cables) + 4 round ports
Cable Sealing Type	Heat shrink
Closure Sealing Type	Dome-to-base clamp with O-ring
Closure Style	Single-ended
Color	Black
Mounting	Pole Strand Wall
Network Area Type	Feeder
Splice Tray Included, quantity	3
Splice Tray Type Included	24-way, heat shrink
Splicing Type, Supported	Single fusion

Dimensions

Length	540 mm 21.26 in
Diameter	150 mm 5.906 in
Main Cable Diameter, maximum	25 mm 0.984 in

EM0055-000 | FOSC100-BM-72

Ordering Tree

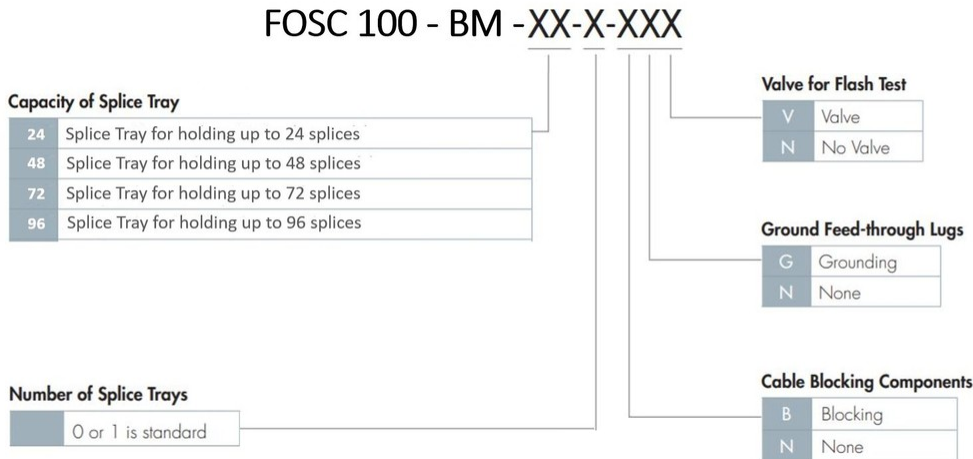

Material Specifications

Material Type Impact-resistant polymer

Environmental Specifications

Environmental Space Below ground | Buried

Water Resistance Flash test valve at 5 psi (40 kPa)

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

