


# PH4088-000 | FIST-GPSTF-12-FAN-N

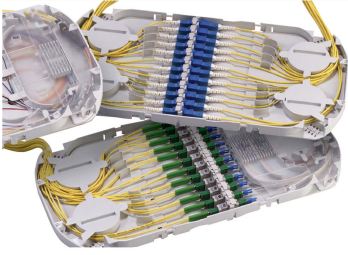

FIST GPST Fiber Termination/Splice Tray, 12/24 ports, no adapters, ANT splice chip, 15 in, gray, left patch cord routing

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Fiber patch/splice tray
<b>Product Brand</b>	FIST®
<b>Product Series</b>	FIST-GPST

## General Specifications

<b>Functionality</b>	Patching   Splicing
<b>Color</b>	Gray
<b>Interface, front</b>	Unloaded
<b>Patch Cord Entry Location</b>	Front, left side
<b>Splicing Type</b>	ANT, single fiber fusion
<b>Total Ports, quantity</b>	12

## Dimensions

<b>Height</b>	16 mm   0.63 in
<b>Width</b>	315 mm   12.402 in
<b>Depth</b>	190 mm   7.48 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

## Environmental Specifications

<b>Operating Temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Storage Temperature</b>	-30 °C to +60 °C (-22 °F to +140 °F)

# PH4088-000 | FIST-GPSTF-12-FAN-N

---

**Relative Humidity** Up to 93%, non-condensing

## Packaging and Weights

**Packaging quantity** 1