


FD3-MM288J00V00E0B

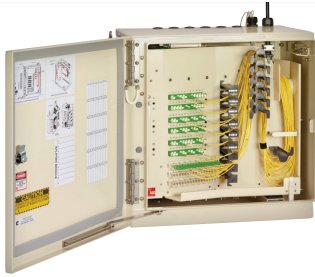

IFDH 3000 Indoor Fiber Distribution Hub, 288F, SC/APC, loose tube /stranded pigtailed, spliced input/dist., 24fFF

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	IFDH 3000

General Specifications

Functionality	Patching Splicing
Access	Front
Adapters, quantity	288
Cable Type	Pigtails - Stranded
Color	Putty white
Distribution Cables, quantity	24
Fibers per Distribution Cable, quantity	12
Fibers per Feeder Cable, quantity	24
Front Door Type	Single hinged
Interface	SC/APC
Mounting	Wall
Port, quantity	288
Splitter Slots, quantity	18

Dimensions

Height	736.6 mm 29 in
Width	533.4 mm 21 in
Depth	368.3 mm 14.5 in
Cable Length	30.48 m 100 ft
Enclosure Size	Medium

FD3-MM288J00V00E0B

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Environmental Space	Indoor
----------------------------	--------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

