


760109975 | 360DM-12SC-SM

G2 LL Singlemode MPO 12 distribution module, 12 SC to 1x12f MPO pinned, dust plugs

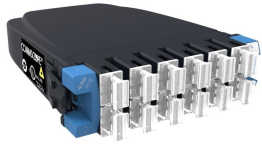

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Series	G2

General Specifications

Color, front	Blue
Color, rear	Gray
Interface, front	SC
Interface Feature, front	UPC
Interface, rear	MPO Pinned
Interface Feature, rear	Key up/up
Polarity	Method B
Shuttered	No
Total Fibers, quantity	12

Dimensions

Height	26 mm 1.024 in
Width	95 mm 3.74 in
Depth	117.7 mm 4.634 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum	1.05 dB

Environmental Specifications

Qualification Standards IEC 61753-1 | TIA-568.3-D

Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1

Weight, net 0.113 kg | 0.249 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

