

# TFP-5TPC8-121B



TFP Fiber Termination/Splice Panel, 144 SC/UPC, preterminated with pigtails, singlemode, 5RU, 19 in, black

## Product Classification

Regional Availability	Latin America   North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	TFP

## General Specifications


Functionality	Patching   Splicing
Body Style	Symmetrical
Color	Black
Interface, front	SC/UPC
Patch Cord Entry Location	Front, left side   Front, right side
Rack Type	EIA 19 in   EIA 23 in
Rack Units	5
Shelf Movement	Fixed
Total Ports, quantity	144

## Dimensions

Height	222.25 mm   8.75 in
Width	482.6 mm   19 in
Depth	399.29 mm   15.72 in

## Ordering Tree

# TFP-5TPC8-121B

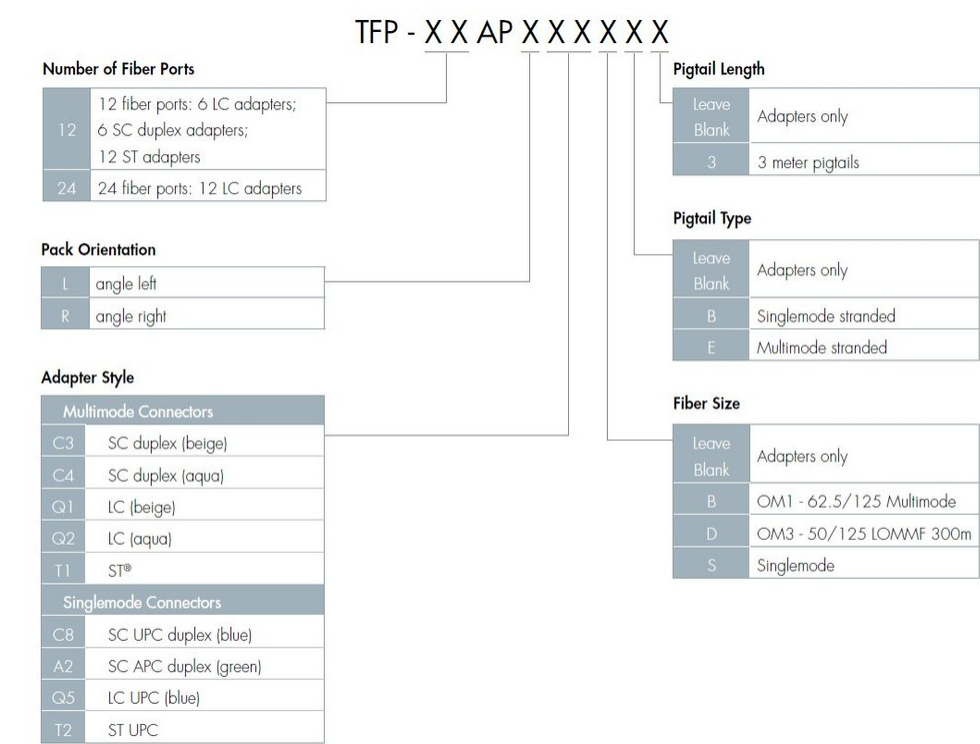

## Material Specifications

Finish	Powder coated
Material Type	Steel

## Optical Specifications

Fiber Mode	Singlemode
------------	------------

## Environmental Specifications

Operating Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

Included	Mounting hardware
Packaging quantity	1
Weight, net	7.194 kg   15.86 lb

## Regulatory Compliance/Certifications

# TFP-5TPC8-121B

---

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

