


FD4M-288S00DDB4P

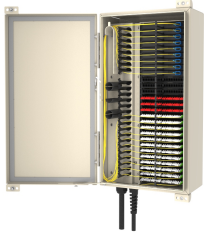

FDH Small 288, 288 distribution fibers, no splitters loaded, LC/APC, dielectric ribbon RBR, 100 ft stub, distribution cable all 288f stub and input cable 72 fiber, Pole/Wall mount

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber distribution hub
Product Series	FDH 5000

General Specifications

Access	Front
Cable Type	Pigtails - Ribbon
Color	Putty white
Distribution Cables, quantity	1
Distribution Ports, quantity	288
Fibers per Distribution Cable, quantity	288
Fibers per Feeder Cable, quantity	72
Mounting	Pole Wall
Splitter Slots, quantity	9

Dimensions

Height	622.3 mm 24.5 in
Width	336.55 mm 13.25 in
Depth	190.5 mm 7.5 in
Cable Length	30.48 m 100 ft
Enclosure Size	Small

Material Specifications

Finish	Powder coated
Material Type	Steel

FD4M-288S00DDB4P

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

