


760236508 | PNL-CS-12SAW

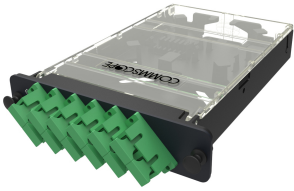

TeraSPEED® Splicing cassette, 12SC APC , No Pigtails

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber cassette |

General Specifications

| | |
|-------------------------------------|------------|
| Adapter Color | Green |
| Interface, front | SC/APC |
| Interface, rear | No pigtail |
| Total Fibers, quantity | 0 |
| Total Ports, quantity, front | 6 |

Dimensions

| | |
|---------------|----------------------|
| Height | 28.956 mm 1.14 in |
| Width | 104.648 mm 4.12 in |
| Depth | 165.354 mm 6.51 in |

Optical Specifications

| | |
|-------------------|------------|
| Fiber Mode | Singlemode |
|-------------------|------------|

Environmental Specifications

| | |
|------------------------|----|
| Safety Standard | UL |
|------------------------|----|

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

Regulatory Compliance/Certifications

| Agency | Classification |
|--------|----------------|
|--------|----------------|

760236508 | PNL-CS-12SAW

| | |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS | Compliant |
| UK-ROHS | Compliant |

