


G22248-000 | CST-B5C1-50C-12T-XXX-RVB

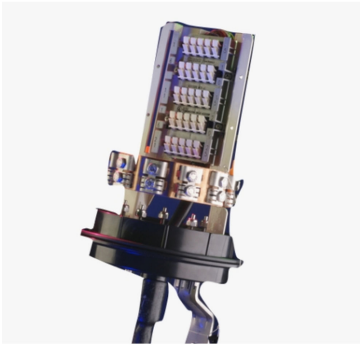

CST Copper Closure kit, re-enterable, 50-pair, filled, shielded cable, 12 ft stub, 20 drop ports

- Requires no additional parts or accessories to install standard 2, 3, 5, or 6 pair service drops
- Craft friendly, tool-less design incorporates the Dat@Term terminal termination system
- Easy to add -up to 20- additional service wires without additional parts
- Universal grommet pre-installed in closure designed to accept round service wires

OBSOLETE

This product was discontinued on: February 28, 2022

Product Classification

Regional Availability	Latin America North America
Product Type	Closure Kit
Product Series	CST

General Specifications

Cable Sealing Type	Gasket/grommet configuration
Closure Style	Single-ended
Color	Black
Mounting	Handhole Manhole Pole
Splicing Capacity, maximum	100

Dimensions

Height	304.8 mm 12 in
Width	190.5 mm 7.5 in

Environmental Specifications

Environmental Space	Aerial Buried
----------------------------	-----------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

G22248-000 | CST-B5C1-50C-12T-XXX-RVB

Packaging Type

Bag | Carton

Weight, net

12 kg | 26.455 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

