


# FFVLC42

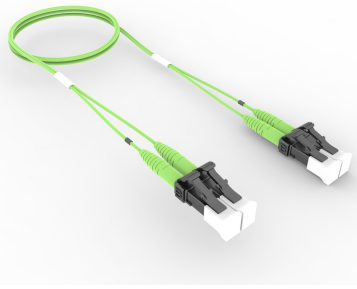

OM5 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Low Smoke Zero Halogen (LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch cord, duplex
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Color, boot A</b>	Lime green
<b>Color, boot B</b>	Lime green
<b>Color, connector A</b>	Black
<b>Color, connector B</b>	Black
<b>Interface, Connector A</b>	LC/UPC
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Pairs, flipped
<b>Total Fibers, quantity</b>	2

## Dimensions

<b>Cable Assembly Length, minimum (ft)</b>	1
<b>Cable Assembly Length, maximum (ft)</b>	999
<b>Cable Assembly Length, minimum (m)</b>	1
<b>Cable Assembly Length, maximum (m)</b>	999
<b>Diameter Over Jacket</b>	1.6 mm   0.063 in

# FFVLC42

## Ordering Tree

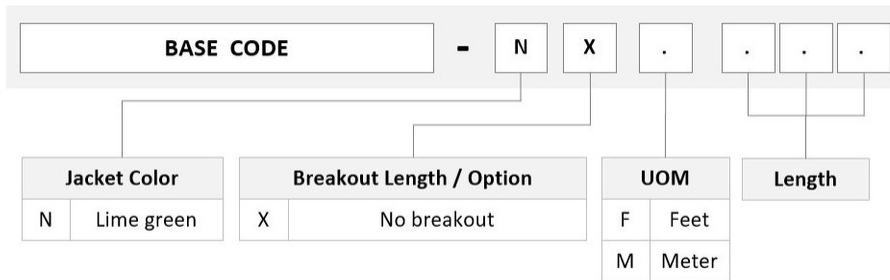

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

ROHS

### Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant/Exempted



## Included Products

760235067 - LazrSPEED® 1.6mm Low Smoke Zero Halogen Riser Zipcord Cable  
N-002-ZC-5G-F16LM/E

# FFVLCLC42

---

860655570

- LC/PC Connector, Multimode, Lime