


FFXLCLC42

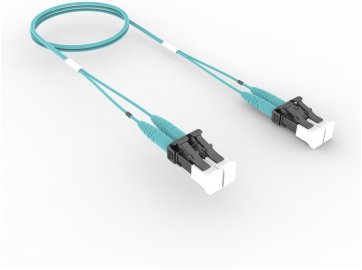

OM4 LC to LC, Fiber Patch Cord, 1.6 mm Duplex, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Replacement for MEA Region: 2105027

General Specifications


Color, boot A	Aqua
Color, boot B	Aqua
Color, connector A	Black
Color, connector B	Black
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped
Total Fibers, quantity	2
Transmission Standards	TIA/EIA-568-C.3

Dimensions

Cable Assembly Length, minimum (ft)	1
Cable Assembly Length, maximum (ft)	999
Cable Assembly Length, minimum (m)	1
Cable Assembly Length, maximum (m)	999
Diameter Over Jacket	1.6 mm 0.063 in

FFXLCLC42

Ordering Tree

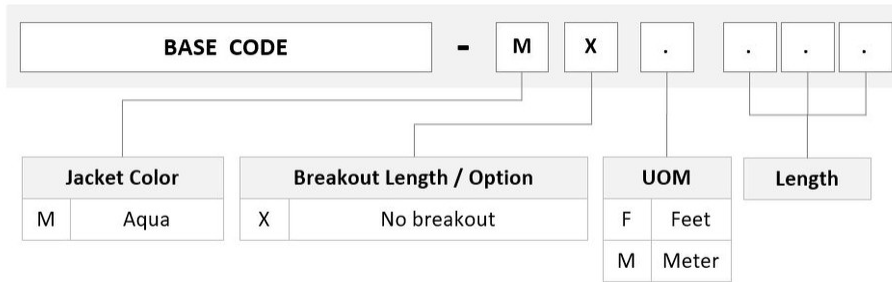

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant



Included Products

FFXLCLC42

- 760021659 - LazrSPEED® 1.6 mm Low Smoke Zero Halogen Riser Zipcord
N-002-ZC-5K-F16AQ/E Cable
- 860655461 - LC/PC Connector, Multimode, Aqua