


FLWMPUCAH

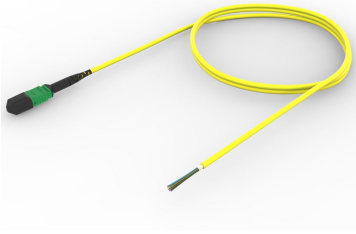

Singlemode MPO (Unpinned) to Unconnectorized, InstaPATCH® 360 Ruggedized Fanout Cable, 48-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Construction Type	Stranded
Fibers per Subunit, quantity	12
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	Unterminated
Jacket Color	Yellow
Polarity	Method B (LL)
Total Fibers, quantity	48

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

FLWMPUCAH

Included Products

- 760038323
P-048-MP-8W-F12YL - Fiber indoor cable, TeraSPEED® Plenum MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Singlemode G.652.D and G.657.A1, Gel-free, Feet jacket marking, Yellow jacket color
- 860366137 - MPO12, LOW LOSS, FEMALE, Singlemode, GREEN, 3mm