

# FSZL2L2WH

LazrSPEED® 300 LC/UPC Keyed Yellow to LC/UPC Keyed Yellow, Distribution Cable, 48-Fiber, Plenum

## Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

## General Specifications


Cable Glands	No glands
Color, connector A	Yellow
Color, connector B	Yellow
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface Feature, connector A	Keyed
Interface, Connector B	LC/UPC
Interface Feature, connector B	Keyed
Total Fibers, quantity	48

## Dimensions

Cable Assembly Length Range (m)	1 – 61
Cable Assembly Length Range (ft)	1 – 200

## Ordering Tree

# FSZL2L2WH

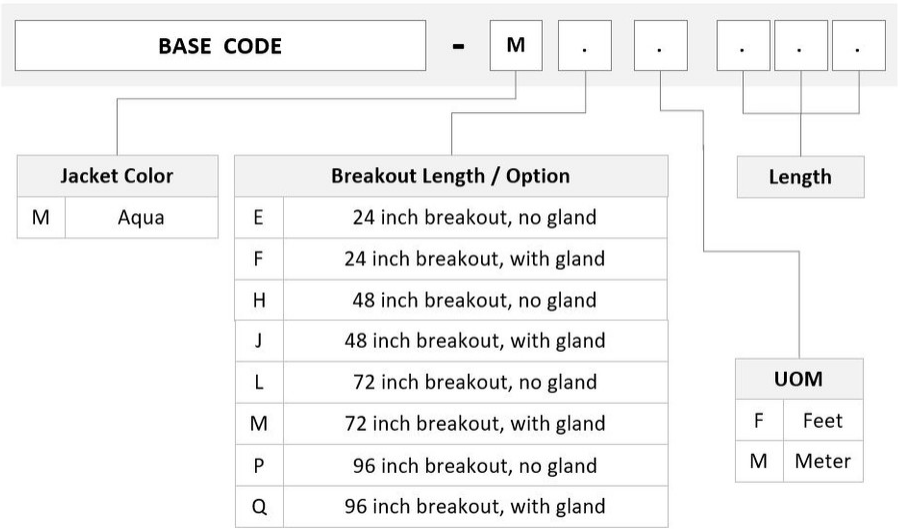

## Mechanical Specifications

**Cable Retention Strength, maximum** 0.50 lb @ 0 ° | 0.50 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM3, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Plenum

## Regulatory Compliance/Certifications

**Agency** ISO 9001:2015  
**Classification** Designed, manufactured and/or distributed under this quality management system



## Included Products

- 760102574 MFC-LCR-09-KYL – LazrSPEED®, OptiSPEED® Pre-Radiused Behind The Wall Keyed LC Connector for 0.9 mm Fiber, multimode, yellow
- P-048-DS-5L-FMU – Fiber indoor cable, LazrSPEED® Plenum Distribution, 48-Fiber Multi-Unit with 12-Fiber Subunits,

# FSZL2L2WH

---

Multimode OM3, Gel-free, Feet jacket marking