


ULXMXSCCF

Base Product

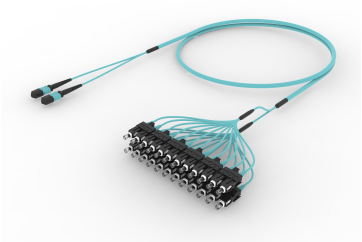

Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to SC/UPC
Ruggedized fanout Cable, 24-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Black
Color, boot B	Blue
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	SC/UPC
Interface Feature, connector B	ULL
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24


Dimensions

Cable Assembly Length Range (m)	3 – 999
---------------------------------	---------

ULXMXSCCF

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

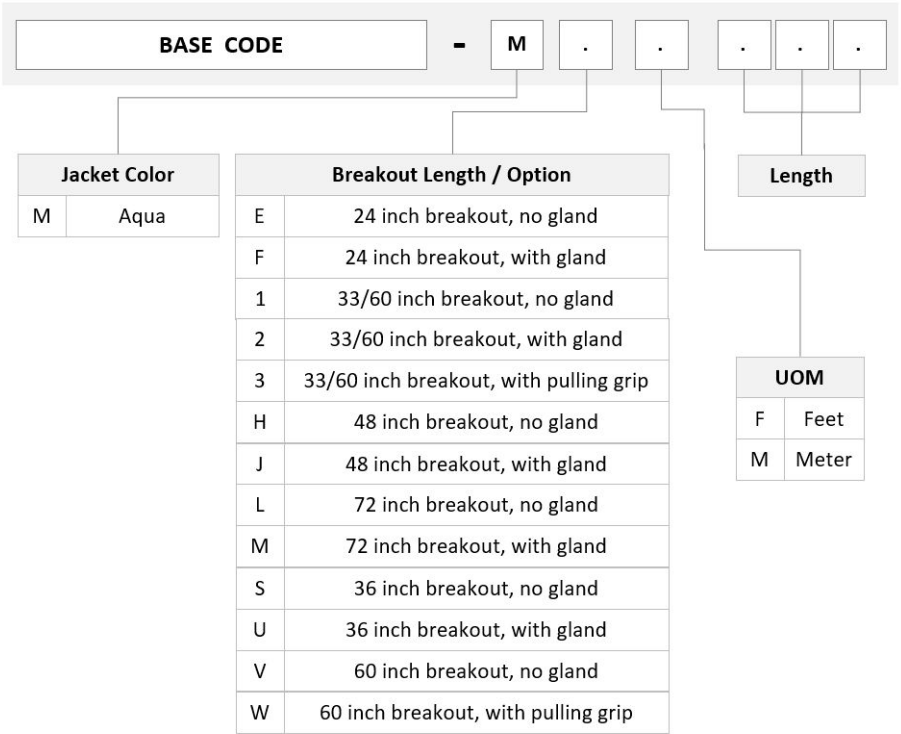

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency ANATEL

Classification Compliant

ULXMXSCCF

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760242114	–	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 24 fiber with 12 fiber subunits, Multimode
P-024-MP-5K-F12AQ/20T		OM4, Feet jacket marking, Aqua jacket color
860659006	–	MPO12, ULL, MALE, OM3/4, AQUA, 2MM