


# UNGSASACM

## Base Product

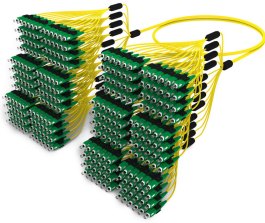

Ultra Low Loss ULL TeraSPEED® SC/APC to SC/APC Ruggedized fanout Cable, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                       |          |
|---------------------------------------|----------|
| <b>Color, boot A</b>                  | Green    |
| <b>Color, connector A</b>             | Green    |
| <b>Color, boot B</b>                  | Green    |
| <b>Color, connector B</b>             | Green    |
| <b>Construction Type</b>              | Stranded |
| <b>Furcation Color</b>                | Yellow   |
| <b>Interface, Connector A</b>         | SC/APC   |
| <b>Interface Feature, connector A</b> | ULL      |
| <b>Interface, Connector B</b>         | SC/APC   |
| <b>Interface Feature, connector B</b> | ULL      |
| <b>Jacket Color</b>                   | Yellow   |
| <b>Fibers per Subunit, quantity</b>   | 12       |
| <b>Total Fibers, quantity</b>         | 144      |

## Dimensions

|   |          |
|---|----------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# UNGSASACM

## Ordering Tree



## Optical Specifications

|                   |                      |
|-------------------|----------------------|
| <b>Fiber Mode</b> | Singlemode           |
| <b>Fiber Type</b> | G.657.A2, TeraSPEED® |

## Environmental Specifications

|   |                                      |
|---|--------------------------------------|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | Dca                                  |
| <b>Environmental Space</b>                          | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

|               |  |
|---------------|--|
| <b>Agency</b> | <b>Classification</b>  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

# UNGSASACM

---

## Included Products

- 760242313  
N-144-MP-8G-F12YL/20T/D – Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk Cable, 144 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating