


URXQPMXHF

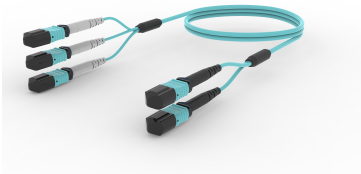

Ultra Low Loss OM4, MPO8 QSFP (Unpinned) to MPO12 (Pinned), Fiber Extension Cable Assembly, 24-Fiber, Low Smoke Zero Halogen

Product Classification

Regional Availability	Australia/New Zealand Europe Latin America Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-12/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

Ordering Tree

URXQPMXHF

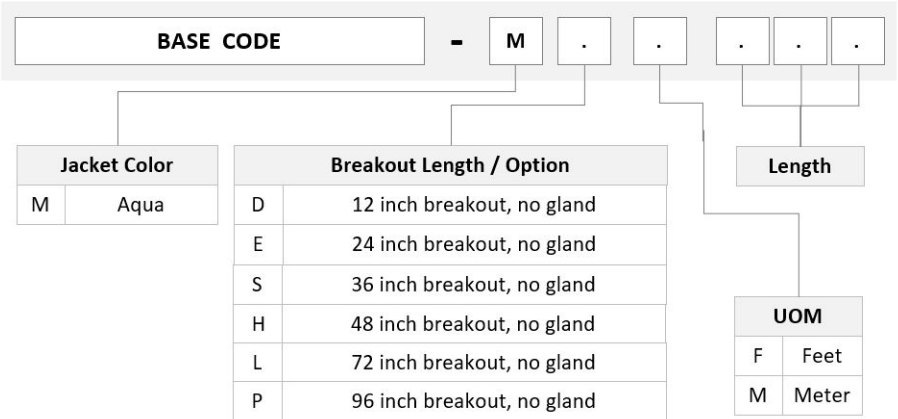

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency ANATEL
Classification Compliant
ISO 9001:2015 Designed, manufactured and/or distributed under this quality management system



Included Products

- 760161786 N-024-MP-5K-F36AQ/D – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 24 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860366210 – MP012, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm

URXQPMXHF

860366228 – MP012, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm