


AQX2X2PHF

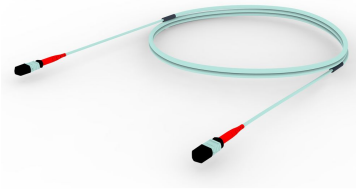

OM4 MPO24 (Pinned) to MPO24 (Unpinned), Fiber Patch Cord, 24-Fiber, Method A, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Red
Color, boot B	Red
Color, connector A	Aqua
Color, connector B	Aqua
Construction Type	Stranded
Fibers per Subunit, quantity	24
Furcation Color	Aqua
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	MPO-24/UPC Female
Jacket Color	Aqua
Polarity	Method A
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

AQX2X2PHF

Ordering Tree

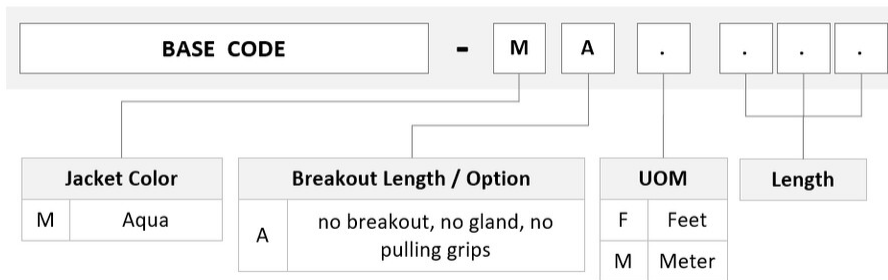

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted



Included Products

- 760161901 - LazrSPEED® Plenum MPO Light Duty Patchcord Cable, 24 fiber
P-024-MP-5K-F36AQ
- 860489111 - LazrSPEED® Elite MPO Female 24 Fiber Connector, aqua
- 860489152 - LazrSPEED® Elite MPO Male 24 Fiber Connector, aqua