


# TP6TB-YL15

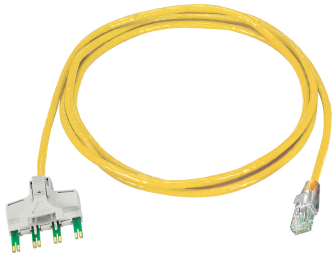

Ultim8 Copper Patch Cord, 4-pair to RJ45, category 6, yellow, 15 ft

## OBSOLETE

This product was discontinued on: December 17, 2020

### Replaced By:

C01G5G2

Highband® Cat6A Patch Cord, Front Facing to RJ45 Plug

## Product Classification

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Regional Availability</b> | Asia   Latin America   North America |
| <b>Product Type</b>          | Twisted pair patch cord              |
| <b>Product Brand</b>         | Ultim 8®                             |

## General Specifications

|                               |                    |
|-------------------------------|--------------------|
| <b>ANSI/TIA Category</b>      | 6                  |
| <b>Cable Type</b>             | U/UTP (unshielded) |
| <b>Conductor Type</b>         | Stranded           |
| <b>Interface, Connector A</b> | 4-pair plug        |
| <b>Interface, Connector B</b> | RJ45 plug          |
| <b>Jacket Color</b>           | Yellow             |
| <b>Pairs, quantity</b>        | 4                  |
| <b>Wiring</b>                 | T568B              |

## Dimensions

|   |                    |
|---|--------------------|
| <b>Cord Length</b>                          | 4.57 m   14.993 ft |
| <b>Compatible Conductor Gauge, stranded</b> | 24 AWG             |

## Material Specifications

|                           |                   |
|---------------------------|-------------------|
| <b>Conductor Material</b> | Tin plated copper |
|---------------------------|-------------------|

# TP6TB-YL15

---

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>Environmental Space</b>   | Non-plenum                           |
| <b>Flammability Rating</b>   | CM                                   |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

