


# FGSB-MSHS-STOR-B

---

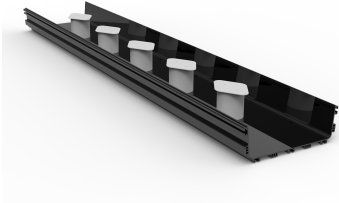

FiberGuide® Slack Storage Straight Section, 4x6in, Black

## OBSOLETE

This product was discontinued on: October 1, 2023

### Replaced By:

FGS-ACC-SPOOL

FiberGuide® Island Spool Kit

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Solid straight with slack storage
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

<b>Product Feature</b>	Snap-together design
<b>Color</b>	Black
<b>Orientation</b>	Horizontal
<b>Section Type</b>	Straight section

## Dimensions

<b>Length</b>	3,657.8 mm   144.008 in
<b>System Dimensions</b>	102 mm x 152 mm (4 in x 6 in)

## Ordering Tree

# FGSB-MSHS-STOR-B

9	10	11
FGS	B	- MSHS -
	F	10

## Section Color

9	empty	yellow
	B	black

## Section Length

11	empty	6 ft
	10	10 ft
	12	12 ft

## Section Size

10	A	4 x 4 in
	B	4 x 6 in
	C	2 x 2 in
	D	4 x 4 in, slotted duct, 2 in slot spacing
	F	4 x 12 in
	F-CF	4 x 12 in, with center divider
	G	2 x 6 in
	H	4 x 24 in
	K	2 x 4 in, slotted duct, 2 in slot spacing
	STOR-B	4 x 6 in, with slack storage spools
	STOR-G	2 x 6 in, with slack storage spools
	STOR-F	4 x 12 in, with slack storage spools

## Material Specifications

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 11.767 kg | 25.942 lb

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](https://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant



