



## COWO Customer Wall Outlet, 1 SC/APC port, no pigtails

- Allows easy and unobtrusive termination of fiber optic cables in an office, home or communications room
- Very flat design, mounts on a standard flush mount electrical outlet
- Possibility to invert the adapter in the holder to prevent disconnection when pulling the patch cords

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Outlet
<b>Product Series</b>	COWO


## General Specifications

<b>Color</b>	White
<b>Cover Type</b>	Hinged with latches
<b>Interface Type</b>	SC/APC
<b>Lock Type</b>	Lead-wire seal   Screw
<b>Mounting</b>	Wall mount
<b>Splices Included, quantity</b>	0
<b>Total Ports, quantity</b>	1

## Dimensions

<b>Height</b>	115.062 mm   4.53 in
<b>Width</b>	80.01 mm   3.15 in
<b>Depth</b>	24.384 mm   0.96 in

## Outline Drawing

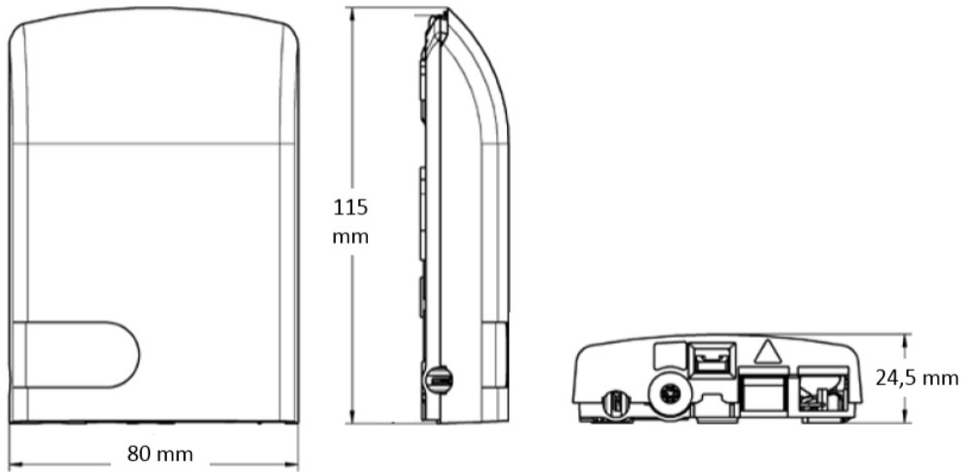

## Material Specifications

**Material Type** LSZH thermoplastic

## Optical Specifications

**Fiber Mode** Singlemode

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Environmental Space** Indoor

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

- CY7021-000 – COWO Customer Wall Outlet, empty, for holding up to 2
- COWO-NN00 adapters

# CY7021-000 | COWO-NN00

---



COWO Customer Wall Outlet, empty, for holding up to 2 adapters

- Allows easy and unobtrusive termination of fiber optic cables in an office, home or communications room
- Very flat design, mounts on a standard flush mount electrical outlet
- Possibility to invert the adapter in the holder to prevent disconnection when pulling the patch cords

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Product Type</b>	Outlet
<b>Product Series</b>	COWO


## General Specifications

<b>Color</b>	White
<b>Cover Type</b>	Hinged with latches
<b>Interface Type</b>	Unloaded
<b>Lock Type</b>	Lead-wire seal   Screw
<b>Mounting</b>	Wall mount
<b>Port Capacity, maximum</b>	4
<b>Splices Included, quantity</b>	0
<b>Total Ports, quantity</b>	0

## Dimensions

<b>Height</b>	115.062 mm   4.53 in
<b>Width</b>	80.01 mm   3.15 in
<b>Depth</b>	24.384 mm   0.96 in

## Outline Drawing

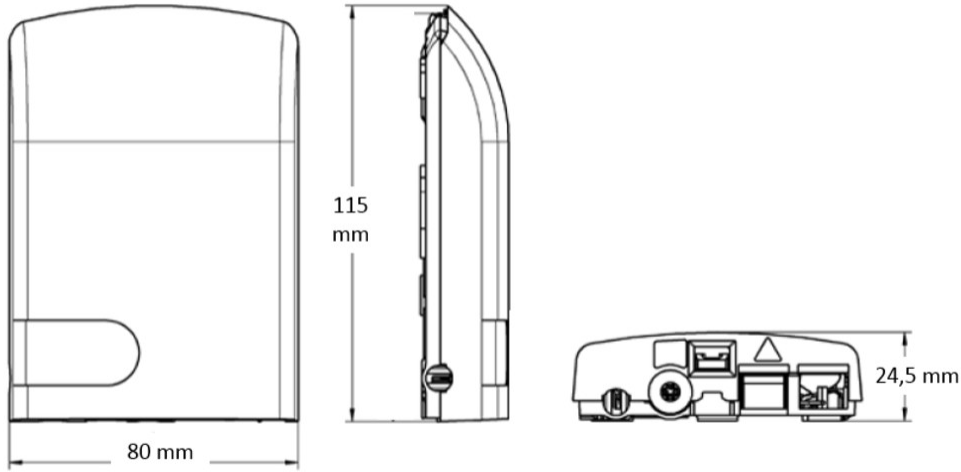

## Material Specifications

**Material Type** LSZH thermoplastic

## Optical Specifications

**Fiber Mode** Singlemode

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Environmental Space** Indoor

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



