


# SEC4-A4B5B1BA000

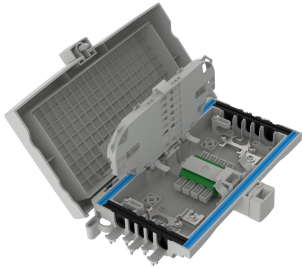

NOVUX™ SEC Closure, splice/patch, 2x LC/APC duplex adapter, 8x LC/APC Grade B 900µm pigtail, no splitters, mounting included, gray

- Design optimized for FTTH façade applications with gray and black colors
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Innovative removable hinge design allows cover to open from the left, right, or top
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Regional Availability Note</b>	Contact your local CommScope representative for specific availability
<b>Product Type</b>	In-line, rectangular fiber closure
<b>Product Brand</b>	NOVUX™
<b>Product Series</b>	SEC100

## General Specifications

<b>Cable Capacity, Branch</b>	2 Round 1.8–7.0 mm (0.07–0.27 in)
<b>Cable Capacity, Drop</b>	6 Round 1.8–7.0 mm (0.07–0.27 in)
<b>Cable Capacity, Feeder</b>	2 Round 9.0–12.0 mm (0.35–0.47 in)
<b>Cable Ports Quantity, total</b>	10 round ports
<b>Cable Sealing Type</b>	Gasket/grommet configuration
<b>Closure Sealing Type</b>	Hinged with lock
<b>Closure Style</b>	In-line
<b>Color</b>	Gray
<b>Mounting</b>	Facade   Wall
<b>Network Area Type</b>	Drop
<b>Port Type</b>	LC/APC
<b>Port, quantity</b>	4
<b>Splice Tray Included, quantity</b>	1
<b>Splice Tray Type Included</b>	12-way, heat shrink
<b>Splices per Tray, quantity</b>	12


# SEC4-A4B5B1BA000

<b>Splicing Capacity, maximum</b>	12
<b>Splicing Capacity, Single Fusion, maximum</b>	12
<b>Splicing Type, Supported</b>	Single fusion
<b>Splitter Type</b>	No splitter
<b>Splitter, quantity</b>	0

## Dimensions

<b>Height</b>	117 mm   4.606 in
<b>Width</b>	210 mm   8.268 in
<b>Depth</b>	50 mm   1.969 in

## Ordering Tree

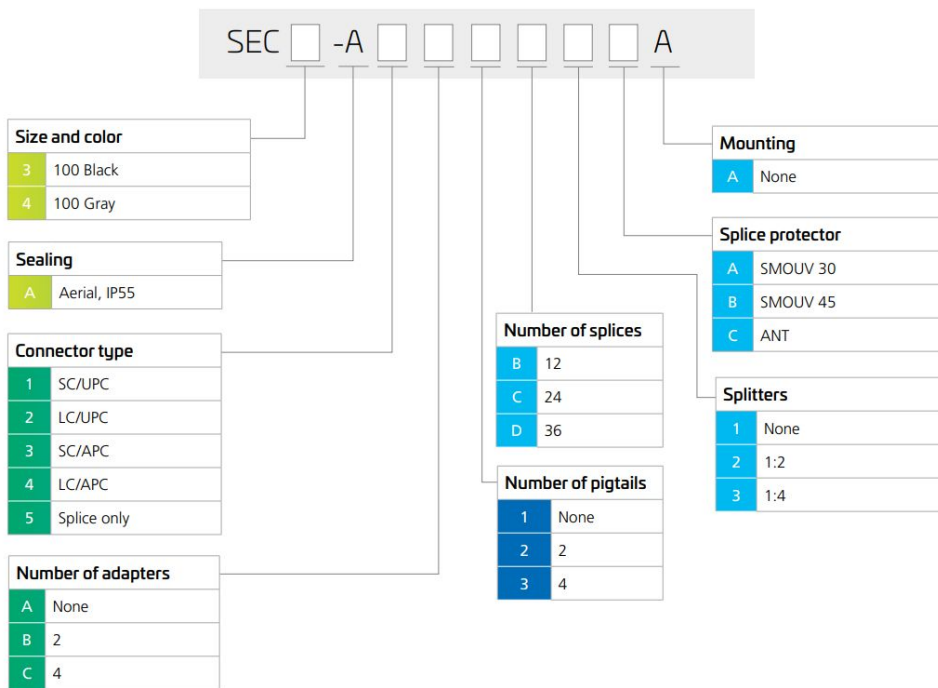

## Optical Specifications

<b>Fiber Type</b>	G.657.A1   G.657.A2   G.657.B3
-------------------	--------------------------------

## Environmental Specifications

<b>Environmental Space</b>	Facade   Outdoor
<b>Qualification Standards</b>	IP55

# SEC4-A4B5B1BA000

---

**UV Resistance** UV stabilized

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Box | Carton

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

