


NG4-MMDKEOR00B

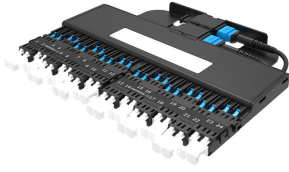

NG4access® MPO Module, singlemode, LC/UPC-MPO 1x24 fiber, Polarity B, right exit (for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	NG4access®
Product Series	NG4

General Specifications

Functionality	Breakout
Application	NG4 MPO module
Adapter Color	Blue
Adapters, quantity, front	12
Body Style	Duplex
Color, front	Black
Color, housing	Black
Color, rear	Black
Interface, front	LC/UPC
Interface, rear	MPO
Interface Feature, rear	Standard
Polarity	Method B Enhanced
Total Fibers, quantity	24
Total Ports, quantity, front	24

Dimensions

Height	13.21 mm 0.52 in
Width	159.77 mm 6.29 in

NG4-MMDKEOR00B

Depth 122.68 mm | 4.83 in

Outline Drawing



Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2

Environmental Specifications

Operating Temperature -5 °C to +40 °C (+23 °F to +104 °F)
Storage Temperature -5 °C to +50 °C (+23 °F to +122 °F)
Relative Humidity Up to 85%, non-condensing

Packaging and Weights

Packaging quantity 1
Packaging Type Bag | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

NG4-MMDKEOR00B

ROHS

Compliant

UK-ROHS

Compliant

