


UGBA-DIN-36

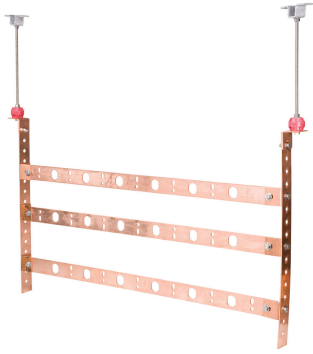

Universal Ground Bar Assembly, three six-position ground bars, for 7-16 DIN or bolt-grounded surge arrestors

OBSOLETE

Product Classification

Product Type	Grounding bar
Ordering Note	CommScope® non-standard product

Dimensions

Height	50.8 mm 2 in
Length	1,003.3 mm 39.5 in
Material Thickness	3.175 mm 0.125 in
Hole Size	1.3 in
Hole Distance, center to center	137.16 mm 5.4 in

Material Specifications

Material Type	Copper
----------------------	--------

Packaging and Weights

Height, packed	1,282.7 mm 50.5 in
Width, packed	68.58 mm 2.7 in
Length, packed	68.58 mm 2.7 in
Included	Bulkhead mounting bar Grounding bar Insulators Mounting brackets Threaded rod Universal hardware
Packaging quantity	1
Weight, gross	8.6 kg 18.96 lb

UGBA-DIN-36

Regulatory Compliance/Certifications

Agency**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

