



FST-T2 Flexible Service Terminal, 12f, 6 Port x 2 Fiber, 6 HMFOC Adapters (Jack/male/pinned), 2 fibers per adapter at drop side, HMFOC Jack (Male/Pinned) Tail at feeder side, black, 30 ft/9 m

- Flexible Service Terminals incorporate hardened connector technology that is designed to withstand the rugged outside plant environment
- Hardened connectors are factory-terminated and environmentally sealed for use in optical drop cable deployments
- Flexible structure allowing installation in constrained spaces

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Access terminal, with multi-fiber port
<b>Product Series</b>	FST-T2
<b>Minimum Order Quantity</b>	1

## General Specifications

<b>Cable Type</b>	Dielectric - Loose Tube
<b>Cable, quantity</b>	7
<b>Distribution Type</b>	6 ports
<b>Drop Port Type</b>	Hardened multi-fiber (HMFOC) adapter
<b>Drop Port, quantity</b>	6
<b>Enclosure Color</b>	Black
<b>Mounting</b>	Handhole   Pedestal
<b>Port Type</b>	Hardened multi-fiber (HMFOC) jack, male/pinned
<b>Port, quantity</b>	6
<b>Splitter, quantity</b>	0
<b>Stub Type</b>	Hardened multi-fiber (HMFOC) jack, pinned

## Dimensions


<b>Height</b>	112.5 mm   4.429 in
<b>Width</b>	53 mm   2.087 in
<b>Depth</b>	31 mm   1.22 in
<b>Cable Length, stub</b>	30 ft (9 m)

# 760245771 | FST-T2-061M1-A0030F

**Cable Outer Diameter**

4.1 x 7.6 mm (0.16 x 0.30 in)

## Ordering Tree

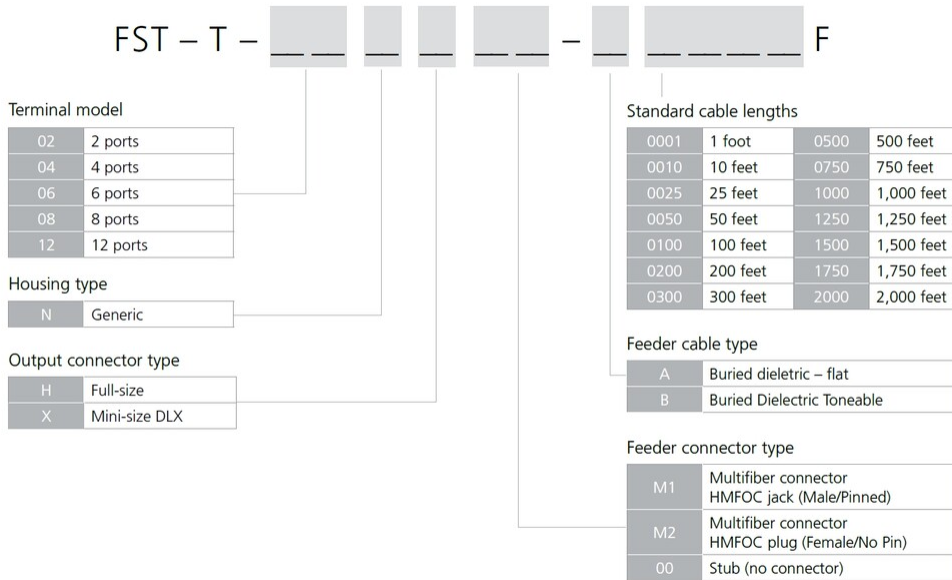

## Material Specifications

**Enclosure Material Type**

Engineered plastic

## Optical Specifications

**Fiber Type**

G.657.A1/A2

**Operating Wavelength Range**

1310 – 1550 nm

**Attenuation Single Ports, maximum**

0.65 dB

**Insertion Loss, Stub Connector, maximum**

0.65 dB

**Return Loss, Connector, minimum**

65 dB

## Environmental Specifications

**Operating Temperature**

-40 °C to +70 °C (-40 °F to +158 °F)

**Relative Humidity**

5%–100%, condensing

**Environmental Space**

Above ground | Below ground | Buried

**Qualification Standards**

IEC 61300, 1 m waterhead | Telcordia GR-3120-CORE | Telcordia GR-3152-CORE

**UV Resistance**

UV stabilized

## Packaging and Weights

**Included**

Mounting hardware

**Packaging quantity**

1

**Packaging Type**

Box | Carton

**Weight, without cable**

0.23 kg | 0.507 lb

## Regulatory Compliance/Certifications

**Agency**

**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

