


# UHVMMXMAH

## Base Product

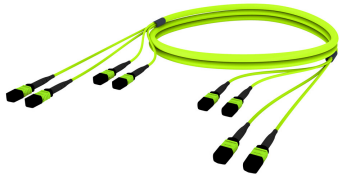

Ultra Low Loss (ULL) Multimode OM5 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 48-Fiber, Plenum

This product will be discontinued on: April 30, 2024

### Replaced By:

UHVMMXCH

Ultra Low Loss (ULL) OM5 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 48-Fiber, Armored Indoor Plenum

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX ULL

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

Connector A, quantity	4
Color, boot A	Black
Color, connector A	Lime green
Connector B, quantity	4
Color, boot B	Black
Color, connector B	Lime green
Construction Type	Armored   Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Male
Interface Feature, connector A	Pinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned

# UHVMMXMAH

---

<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	48

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
------------------------------------------	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor   Plenum

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760230235 P-048-MZ-5G-F12LM	–	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, Multimode OM5, 48 fiber multi-unit with 12 fiber subunits, Lime-green jacket color, Feet cable marking
--------------------------------	---	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

# UHVMMXMAH

---

860617240

– MP012, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm