


760253156 | OCP-L1-02MASEN-XX-(100)

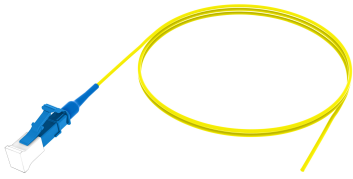

Fiber Optic Pigtail, Simplex, Singlemode, LC/UPC to Stub, 0.9 mm diameter, 2 m, Kit of 100 pigtails

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP


General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	LC/UPC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	2 m 6.562 ft
--------------------	----------------

Ordering Tree

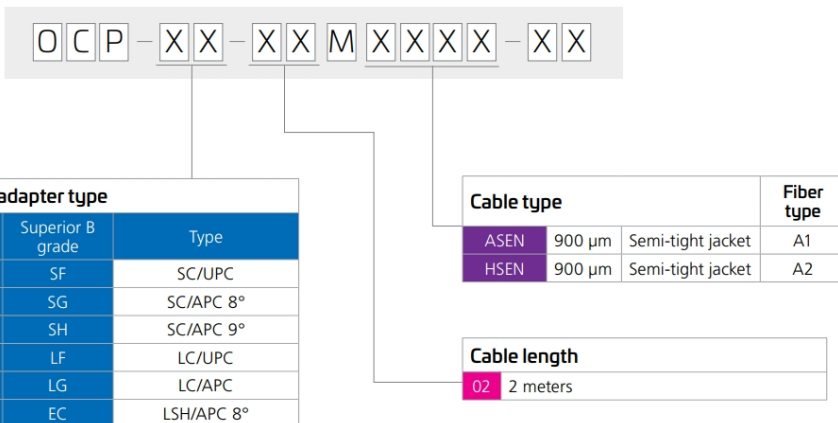

- Standard Configuration by default 900μm buffer
 buffer color : yellow
 250 μm color : natural or milky white

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	100
---------------------------	-----

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

