

Ultra Low Loss (ULL) OM5 MPO8 (Non-Pinned) to unconnectorized, Fiber Trunk Cable Assembly, 192-Fiber, LZSH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, connector A	Lime green
Connector A, quantity	24
Connector B, quantity	0
Construction Type	Stranded
Fibers per Subunit, quantity	8
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	Unterminated
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	192

Dimensions

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

# U3VQPUCTN

## Ordering Tree

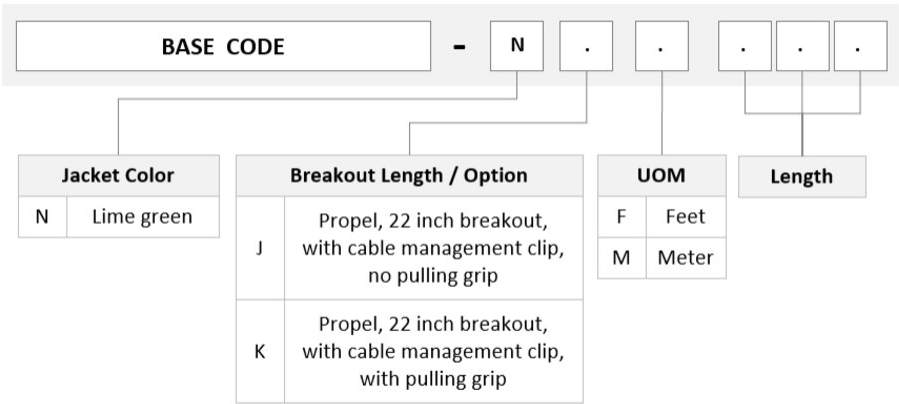

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**EN50575 CPR Cable EuroClass Fire Performance** B2ca  
**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency** ISO 9001:2015  
**Classification** Designed, manufactured and/or distributed under this quality management system



## Included Products

760253115 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 192 fiber with 2.0 mm Subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, B2ca  
N-192-MP-5G-F08LM/20T/B2

# U3VQPUCTN

---

860659026

- Flame rating
- MPO-08, ULTRA LOW LOSS, FEMALE, OM5, LIME-GREEN, 2mm