

# U3VQVQZT8



Ultra Low Loss (ULL) OM5 MPO8 APC (Non-Pinned) to MPO8 APC (Pinned), Fiber Trunk Cable Assembly, 8-Fiber, LSZH B2ca

## Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Gray
Color, boot B	Gray
Color, connector A	Green
Color, connector B	Green
Connector A, quantity	1
Connector B, quantity	1
Construction Type	Stranded
Fibers per Subunit, quantity	8
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	8


## Dimensions

Breakout Length	22 in
-----------------	-------

# U3VQVQZT8

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

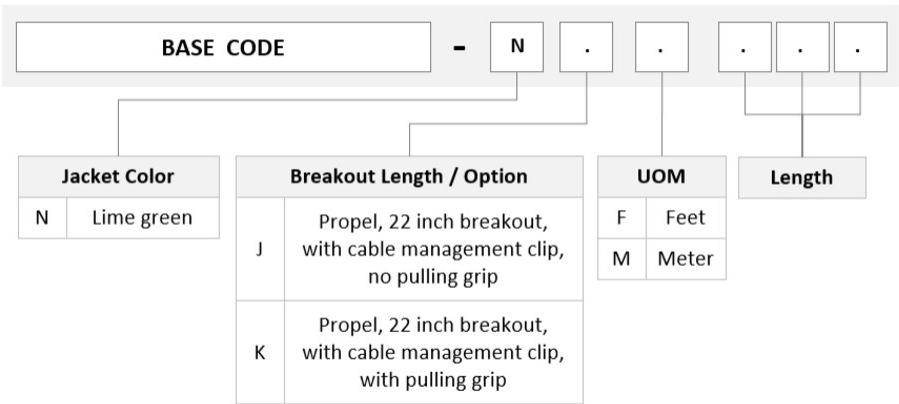

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

# U3VQVQZT8



## Included Products

- |                          |   |  |
|--------------------------|---|--|
| 760253106                | – | LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable with 2.0mm Subunits, 8 fiber |
| N-008-MP-5G-F08LM/20T/B2 |   |  |
| 860662230                | – | MPO8,ULL,MM,MALE,APC,GREEN,2MM   |
| 860662232                | – | MPO8,ULL,MM,FEMALE,APC,GREEN,2MM   |