


U3XQVQZTL

Base Product

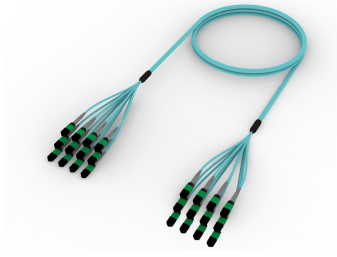

Ultra Low Loss (ULL) OM4 MPO8 APC (Non-Pinned) to MPO8 APC (Pinned), Fiber Trunk Cable Assembly, 96-Fiber, LSZH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	12
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	12
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	96

Dimensions

Breakout Length	22 in
------------------------	-------

U3XQVQZTL

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
------------------------------------------	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

- | | | |
|---------------------------------------|---|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 760253123
N-096-MP-5K-F08AQ/20T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber with 2.0 mm Subunits, 96 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860662230 | - | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm |
| 860662232 | - | MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm |