


UQXQPQPF8

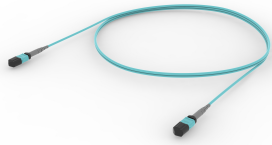

Ultra Low Loss (ULL) OM4 MPO8 (Non-Pinned) to MPO8 (Non-Pinned), Fiber Array Cable Assembly, 8-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	1
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	MPO-08/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	3 – 999

UQXQPQPF8

Ordering Tree

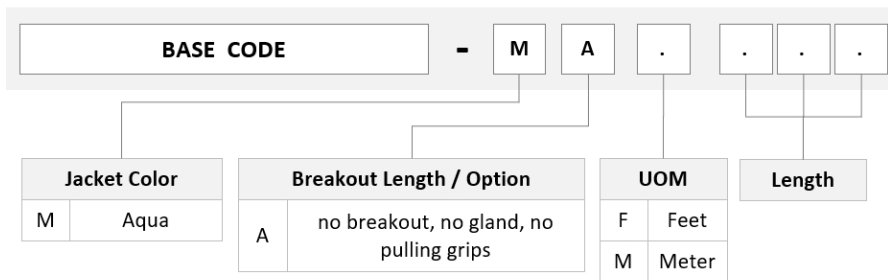

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015



Classification

Compliant

Designed, manufactured and/or distributed under this quality management system

Included Products

- 760248403 P-008-MP-5K-F20AQ – Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 8 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color
- 860659024 – MPO-08, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 2mm