


# UQXQVLUF8

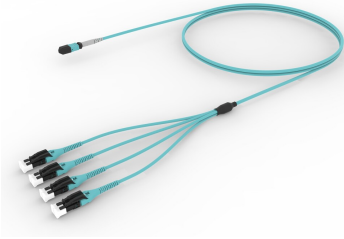

Ultra Low Loss (ULL) OM4 MPO8 APC (Non-Pinned) to LC/UPC Uniboot, Fiber Array Cable Assembly, 8-Fiber, Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	8
<b>Color, boot B</b>	Aqua
<b>Color, connector B</b>	Black
<b>Construction Type</b>	Stranded
<b>Fibers per Subunit, quantity</b>	8
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/APC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	8

## Dimensions

# UQXQVLUF8

<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
<b>Cable Assembly Length Range (m)</b>	1 – 305
<b>Cable Assembly Length Range (ft)</b>	1 – 999

## Ordering Tree

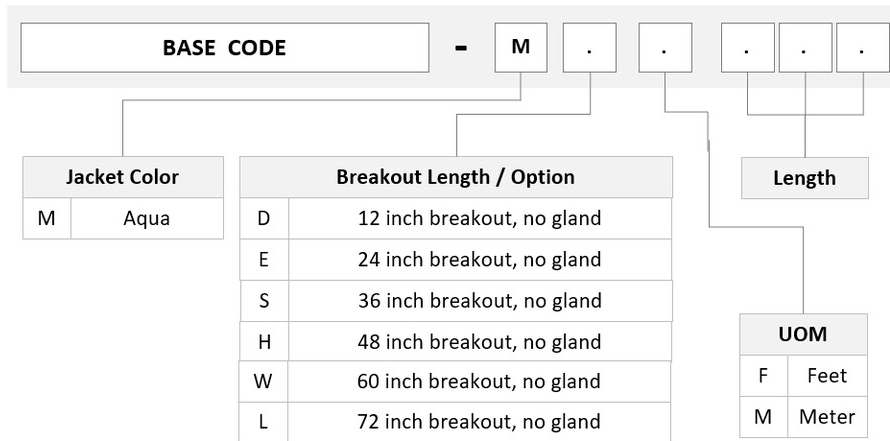

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor   Plenum

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



# UQXQVLUF8

---

## Included Products

- 760248403  
P-008-MP-5K-F20AQ - Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 8 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color
- 860658161 - 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua
- 860662232 - MPO8,U LL,Multimode,FEMALE,APC,GREEN,2 mm