


URGMPLUUD

Base Product

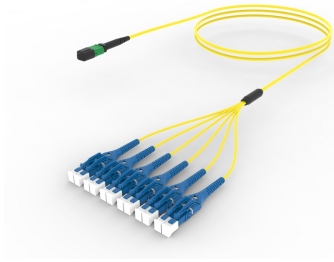

Ultra Low Loss (ULL) Singlemode MPO12 (Non-pinned) to LC Uniboot, Fiber Array Cable Assembly, 12-Fiber, Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	1
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	6
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

URGMPLUUD

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

Ordering Tree

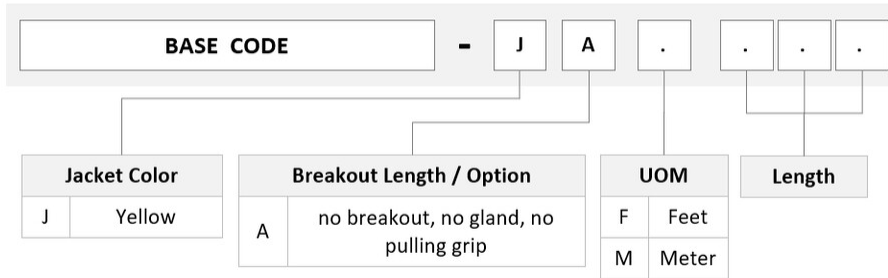

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



URGMPLUUD

Included Products

- 760245203 – Low Smoke Zero Halogen Riser Light Duty Interconnect Cable, 12 fiber
- N-012-MP-8G1-F20YL/E
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
- 860658160 – LC/UPC Uniboot Connector, Singlemode, Blue