


UGBA-36

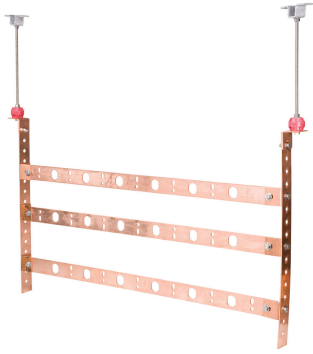

Universal Ground Bar Assembly, three six-position ground bars, for 7-16 DIN, type N, or bolt-grounded surge arrestors

OBSOLETE

Product Classification

Product Type	Grounding bar
Ordering Note	CommScope® non-standard product

Dimensions

Height	50.8 mm 2 in
Length	457.2 mm 18 in
Material Thickness	6.35 mm 0.25 in
Hole Size	1.3 in
Hole Distance, center to center	63.5 mm 2.5 in

Material Specifications

Material Type	Copper
----------------------	--------

Packaging and Weights

Height, packed	655.32 mm 25.8 in
Width, packed	248.92 mm 9.8 in
Length, packed	58.42 mm 2.3 in
Included	Bulkhead mounting bar Grounding bar Insulators Mounting brackets Threaded rod Universal hardware
Packaging quantity	1
Weight, gross	7.7 kg 16.976 lb

UGBA-36

Regulatory Compliance/Certifications

Agency**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

